


RNA2207-2RSR

Yoke type track roller

Schaeffler ID:
0007104660000

Yoke type track rollers RNA22...-2RSR,
without axial guidance, lip seals on both
sides

Technical information

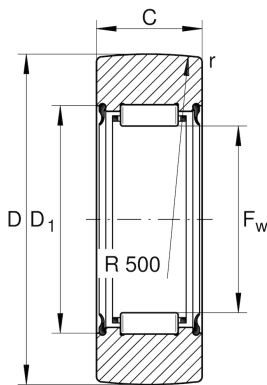

Main Dimensions & Performance Data

D	72 mm	Outside diameter
F _w	42 mm	Under roller diameter
C	22,7 mm	Width, outer ring
C _{r w}	21.500 N	Basic dynamic load rating, radial
C _{0r w}	36.500 N	Basic static load rating, radial
C _{ur w}	5.300 N	Fatigue load limit, radial
n _{D G}	1.100 1/min	Speed on permanent grease lubrication
	0,515 kg	Weight

Dimensions

D _{1 min}	50 mm	Minimum mounting dimension
r _{min}	1,1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile