



★ KSR15-B0-10-10-14-08


Roller chain idler sprocket unit

Schaeffler ID:
0008341060000

Roller chain idler sprocket units KSR...-B0,
sprocket made from steel or sintered iron

★ Preferred product

Technical information

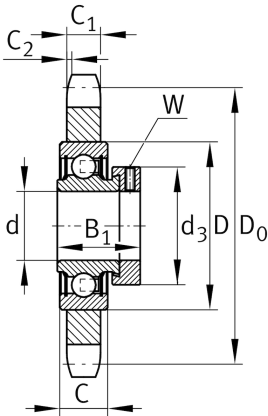

Main Dimensions & Performance Data

d	15 mm	Bore diameter
d	0,018 mm	Upper tolerance
d	0 mm	Lower tolerance
C ₁	8,7 mm	Thickness of sprocket
D ₀	71,3 mm	Pitch circle diameter (gearing)
D _k	78 mm	Tip diameter (gearing)
	0,52 kg	Weight

Dimensions

C ₂	1,3 mm	Chamfer width
D	40 mm	Outside diameter
B ₁	28,3 mm	Locking collar total width
C	12 mm	Width, outer ring
d ₃	28,4 mm	Outside diameter locking collar/locknut
d ₃	28,4 mm	Outside diameter eccentric locking collar
W	3 mm	Width of flats
B ₁	28,3 mm	Locking collar width

Mounting dimensions

p	0,625 Inch	Tooth set
z	14	Number of teeth
	x	ISO chain
	x	ANSI chain
W	M6 X 0,75 mm	Width accros flats