



★ KSR16-L0-08-10-16-22


Roller chain idler sprocket unit

Schaeffler ID:
0009517490000

Roller chain idler sprocket units KSR...-L0...-22, sprocket made from plastic

★ Preferred product

Technical information

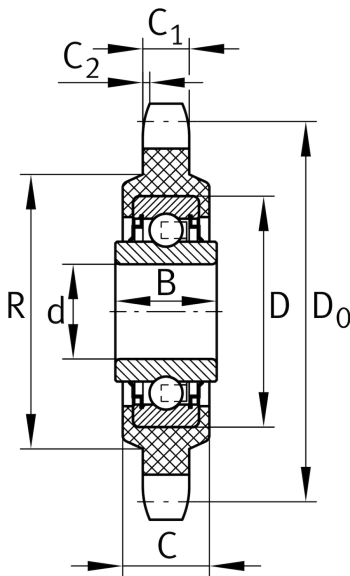

Main Dimensions & Performance Data

d	16,2 mm	Bore diameter
d	0,1 mm	Upper tolerance
d	0 mm	Lower tolerance
C ₁	7 mm	Thickness of sprocket
D ₀	65,1 mm	Pitch circle diameter (gearing)
D _k	70,5 mm	Tip diameter (gearing)
	0,097 kg	Weight

Dimensions

C ₂	1,1 mm	Chamfer width
D	40 mm	Outside diameter
C	18,1 mm	Width, outer ring
R	48 mm	Heeldiameter sprocket
B	18,3 mm	Width inner ring

Mounting dimensions

p	0,5 Inch	Tooth set
z	16	Number of teeth
	x	ISO chain
	x	ANSI chain