



★ RSRD25-150-L0


Idler pulley units

Schaeffler ID:
0008346020000

Belt tension pulleys RSRD...-L0, for round belts, steel cables and hemp ropes

★ Preferred product

Technical information

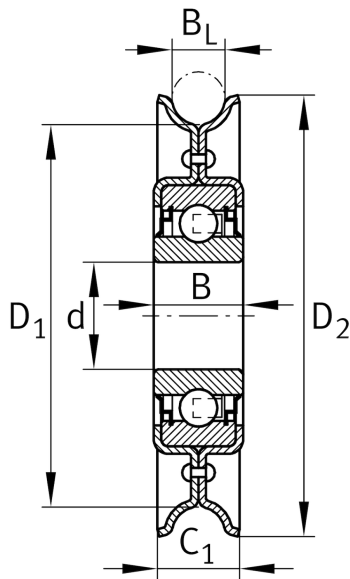

Main Dimensions & Performance Data

d	25 mm	Bore diameter
d	0 mm	Upper tolerance
d	-0,01 mm	Lower tolerance
D ₁	133 mm	Raceway diameter idler pulley
C ₁	24 mm	Width idler pulley
C _r	14.000 N	Basic dynamic load rating, radial
C _{0r}	7.800 N	Basic static load rating, radial
C _{ur}	410 N	Fatigue load limit, radial
	0,78 kg	Weight

Dimensions

D ₂	154 mm	Outside diameter idler pulley
B	21 mm	Width
B _L	17 mm	Width idler pulley raceway