




## RSRD20-160-L0

### Idler pulley units

Schaeffler ID:  
0008345990000

Belt tension pulleys RSRD..-L0, for round belts, steel cables and hemp ropes

### Technical information

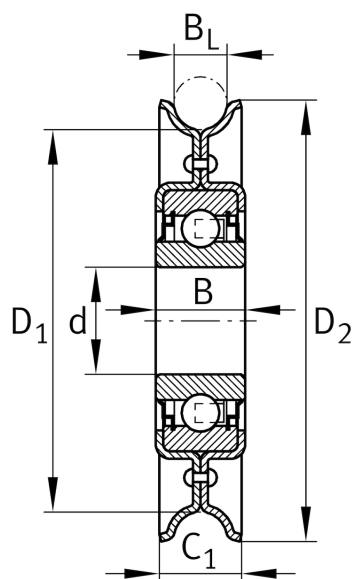

### Main Dimensions & Performance Data

d	20 mm	Bore diameter
d	0 mm	Upper tolerance
d	-0,01 mm	Lower tolerance
D <sub>1</sub>	136,5 mm	Raceway diameter idler pulley
C <sub>1</sub>	17,5 mm	Width idler pulley
C <sub>r</sub>	12.800 N	Basic dynamic load rating, radial
C <sub>0r</sub>	6.600 N	Basic static load rating, radial
C <sub>ur</sub>	345 N	Fatigue load limit, radial
	0,61 kg	Weight

### Dimensions

D <sub>2</sub>	155,8 mm	Outside diameter idler pulley
B	17,7 mm	Width
B <sub>L</sub>	13,5 mm	Width idler pulley raceway