



★ RSRB13-159-L0


Idler pulley units

Schaeffler ID:
0008345210000

Idler pulley units RSRB...L0

★ Preferred product

Technical information

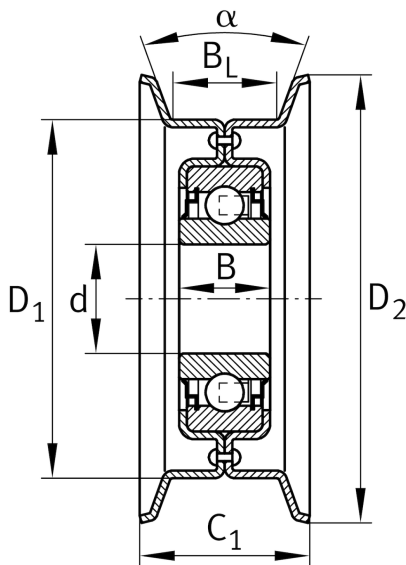

Main Dimensions & Performance Data

d	13 mm	Bore diameter
d	0,08 mm	Upper tolerance
d	-0,05 mm	Lower tolerance
D ₁	139,7 mm	Raceway diameter idler pulley
C ₁	36,5 mm	Width idler pulley
C _r	9.800 N	Basic dynamic load rating, radial
C _{0r}	4.750 N	Basic static load rating, radial
C _{ur}	248 N	Fatigue load limit, radial
	0,7 kg	Weight

Dimensions

D ₂	159 mm	Outside diameter idler pulley
B	18,3 mm	Width
B _L	25,4 mm	Width idler pulley raceway

Mounting dimensions

a	10 °	Angle idler pulley raceway
---	------	----------------------------