



★ RSRB15-92-L0


Idler pulley units

Schaeffler ID:
0008344240000

Idler pulley units RSRB...L0

★ Preferred product

Technical information

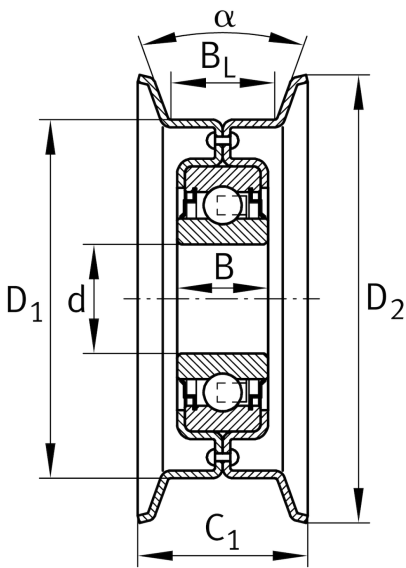

Main Dimensions & Performance Data

| | | |
|-----------------|----------|-----------------------------------|
| d | 15 mm | Bore diameter |
| d | 0,08 mm | Upper tolerance |
| d | -0,05 mm | Lower tolerance |
| D ₁ | 76,2 mm | Raceway diameter idler pulley |
| C ₁ | 31 mm | Width idler pulley |
| C _r | 7.600 N | Basic dynamic load rating, radial |
| C _{0r} | 3.700 N | Basic static load rating, radial |
| C _{ur} | 193 N | Fatigue load limit, radial |
| | 0,28 kg | Weight |

Dimensions

| | | |
|----------------|---------|-------------------------------|
| D ₂ | 92 mm | Outside diameter idler pulley |
| B | 14,4 mm | Width |
| B _L | 22,2 mm | Width idler pulley raceway |

Mounting dimensions

| | | |
|---|------|----------------------------|
| a | 10 ° | Angle idler pulley raceway |
|---|------|----------------------------|