



## ★ RSRB16-159-L0


Idler pulley units

Schaeffler ID:  
0008344590000

Idler pulley units RSRB...L0

★ Preferred product

### Technical information

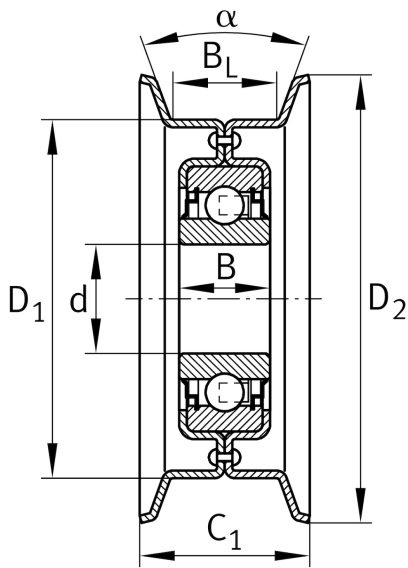

#### Main Dimensions & Performance Data

d	16 mm	Bore diameter
d	0,26 mm	Upper tolerance
d	0,13 mm	Lower tolerance
D <sub>1</sub>	139,7 mm	Raceway diameter idler pulley
C <sub>1</sub>	36,5 mm	Width idler pulley
C <sub>r</sub>	9.800 N	Basic dynamic load rating, radial
C <sub>0r</sub>	4.750 N	Basic static load rating, radial
C <sub>ur</sub>	248 N	Fatigue load limit, radial
	0,7 kg	Weight

#### Dimensions

D <sub>2</sub>	159 mm	Outside diameter idler pulley
B	18,3 mm	Width
B <sub>L</sub>	25,4 mm	Width idler pulley raceway

#### Mounting dimensions

a	10 °	Angle idler pulley raceway
---	------	----------------------------