



★ RSRA15-90-L0


Idler pulley units

Schaeffler ID:
0008344320000

Idler pulley units RSRA...-L0

★ Preferred product

Technical information

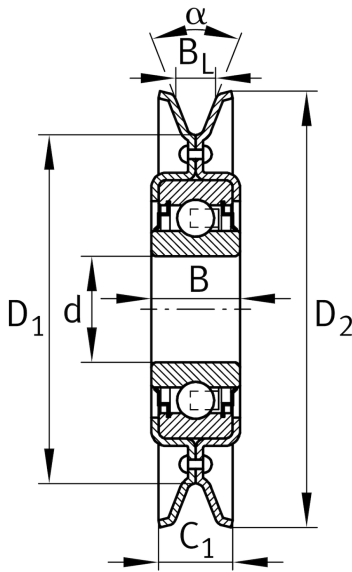

Main Dimensions & Performance Data

d	15 mm	Bore diameter
d	0,08 mm	Upper tolerance
d	-0,05 mm	Lower tolerance
D ₁	61,6 mm	Raceway diameter idler pulley
C ₁	20 mm	Width idler pulley
C _r	7.600 N	Basic dynamic load rating, radial
C _{0r}	3.700 N	Basic static load rating, radial
C _{ur}	193 N	Fatigue load limit, radial
	0,22 kg	Weight

Dimensions

D ₂	90 mm	Outside diameter idler pulley
B	14,4 mm	Width
B _L	12,4 mm	Width idler pulley raceway

Mounting dimensions

a	32 °	Angle idler pulley raceway
	8, 10, (12,5)	Vee belt size