



★ RSRA13-129-L0-L114


Idler pulley units

Schaeffler ID:
0009763260000

Idler pulley units RSRA...L0

★ Preferred product

Technical information

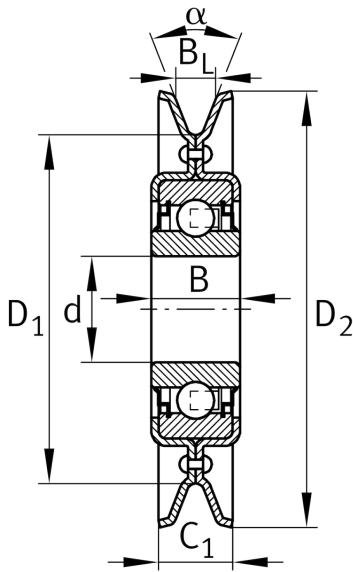

Main Dimensions & Performance Data

d	13 mm	Bore diameter
d	0,08 mm	Upper tolerance
d	-0,05 mm	Lower tolerance
D ₁	73,7 mm	Raceway diameter idler pulley
C ₁	32 mm	Width idler pulley
C _r	10.100 N	Basic dynamic load rating, radial
C _{0r}	4.750 N	Basic static load rating, radial
C _{ur}	248 N	Fatigue load limit, radial
	0,2 kg	Weight

Dimensions

D ₂	129 mm	Outside diameter idler pulley
B	18,3 mm	Width
B _L	22,1 mm	Width idler pulley raceway

Mounting dimensions

a	32 °	Angle idler pulley raceway
	13, 17, 20, 22	Vee belt size