



★ RSRA16-129-L0


Idler pulley units

Schaeffler ID:
0008344830000

Idler pulley units RSRA...L0

★ Preferred product

Technical information

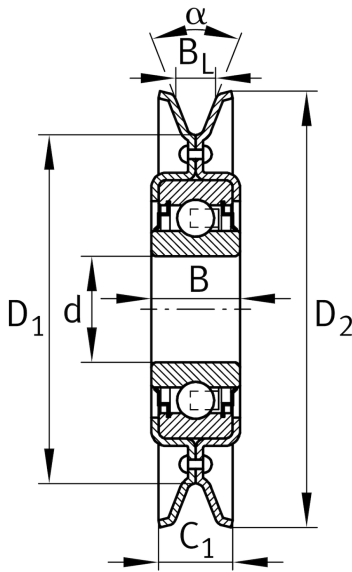

Main Dimensions & Performance Data

| | | |
|-----------------|---------|-----------------------------------|
| d | 16 mm | Bore diameter |
| d | 0,26 mm | Upper tolerance |
| d | 0,13 mm | Lower tolerance |
| D ₁ | 73,7 mm | Raceway diameter idler pulley |
| C ₁ | 32 mm | Width idler pulley |
| C _r | 9.800 N | Basic dynamic load rating, radial |
| C _{0r} | 4.750 N | Basic static load rating, radial |
| C _{ur} | 248 N | Fatigue load limit, radial |
| | 0,54 kg | Weight |

Dimensions

| | | |
|----------------|---------|-------------------------------|
| D ₂ | 129 mm | Outside diameter idler pulley |
| B | 18,3 mm | Width |
| B _L | 22,1 mm | Width idler pulley raceway |

Mounting dimensions

| | | |
|---|----------------|----------------------------|
| a | 32 ° | Angle idler pulley raceway |
| | 13, 17, 20, 22 | Vee belt size |