

★ RNA22/8-2RSR


Yoke type track roller

Schaeffler ID:
0000271700000

★ Preferred product

Yoke type track rollers RNA22...-2RSR,
without axial guidance, lip seals on both
sides

Technical information

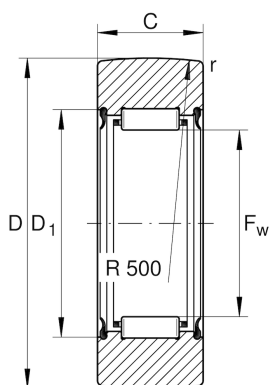

Main Dimensions & Performance Data

D	24 mm	Outside diameter
F_w	12 mm	Under roller diameter
C	11,8 mm	Width, outer ring
$C_{r w}$	4.800 N	Basic dynamic load rating, radial
$C_{0r w}$	4.300 N	Basic static load rating, radial
$C_{ur w}$	650 N	Fatigue load limit, radial
n_{DG}	7.000 1/min	Speed on permanent grease lubrication
	25,3 g	Weight

Dimensions

$D_{1 \min}$	18 mm	Minimum mounting dimension
r_{\min}	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile