



## ★ NA22/8-2RSR


Yoke type track roller

Schaeffler ID:  
0000275700000

★ Preferred product

Yoke type track rollers NA22...-2RSR,  
without axial guidance, lip seals on both  
sides

### Technical information

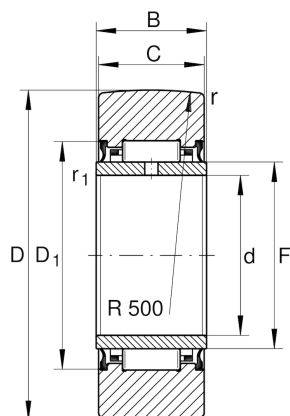

### Main Dimensions & Performance Data

D	24 mm	Outside diameter
F	12 mm	Raceway diameter inner ring
C	11,8 mm	Width, outer ring
$C_{r w}$	4.800 N	Basic dynamic load rating, radial
$C_{0 r w}$	4.300 N	Basic static load rating, radial
$C_{u r w}$	650 N	Fatigue load limit, radial
$n_{D G}$	7.000 1/min	Speed on permanent grease lubrication
	32 g	Weight

### Dimensions

d	8 mm	Bore diameter
B	12 mm	Width, inner ring
$D_{1 \min}$	18 mm	Minimum mounting dimension
$r_{\min}$	0,3 mm	Minimum chamfer dimension
$r_{1 \min}$	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile