

★ KR19-PP


Yoke type track roller

Schaeffler ID:
0055453820000

★ Preferred product

Stud type track rollers KR...-PP, with axial guidance, plastic axial plain washers on both sides, optimized INA-profile

Technical information

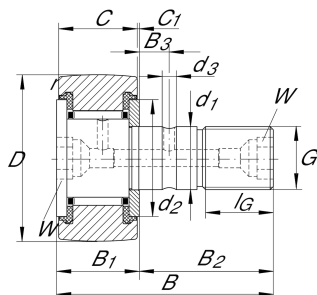

Main Dimensions & Performance Data

D	19 mm	Outside diameter
d ₁	8 mm	Fit diameter of roller stud / stud
B	32 mm	Width
C _{r w}	3.500 N	Basic dynamic load rating, radial
C _{0r w}	4.050 N	Basic static load rating, radial
C _{ur w}	550 N	Fatigue load limit, radial
n _{D G}	11.000 1/min	Speed on permanent grease lubrication
	27,949 g	Weight

Dimensions

B ₁	12,2 mm	Maximum width of thrust washer
B ₂	20 mm	Bolt/stud length effectively
C	11 mm	Width, outer ring
C ₁	0,6 mm	Protrusion outer ring to thrust washer
r _{min}	0,15 mm	Minimum chamfer dimension
d ₂	15 mm	Stop diameter of thrust washer
G	M8	Thread
l _G	10 mm	Thread length

Additional information

	NIPA1	Drive-fit lubrication nipple
	1,5 mm	Protrusion lubrication nipple
M _A	8 Nm	Tightening torque nut