



## ★ KRE19-PP


### Yoke type track roller

Schaeffler ID:  
0057421290000

★ Preferred product

Stud type track rollers KRE...-PP, with axial guidance, with eccentric collar, plastic axial plain washers on both sides

## Technical information

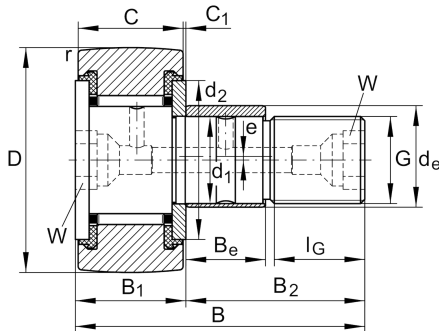

### Main Dimensions & Performance Data

D	19 mm	Outside diameter
d <sub>1</sub>	8 mm	Fit diameter of roller stud / stud
B	32 mm	Width
C <sub>rw</sub>	3.500 N	Basic dynamic load rating, radial
C <sub>orw</sub>	4.050 N	Basic static load rating, radial
C <sub>urw</sub>	550 N	Fatigue load limit, radial
n <sub>DG</sub>	11.000 1/min	Speed on permanent grease lubrication
	31,01 g	Weight

### Dimensions

B <sub>1</sub>	12,2 mm	Width of thrust washer
B <sub>2</sub>	20 mm	Bolt/stud length effectively
C	11 mm	Width, outer ring
C <sub>1</sub>	0,6 mm	Protrusion outer ring to thrust washer
r <sub>min</sub>	0,15 mm	Minimum chamfer dimension
d <sub>2</sub>	15 mm	Stop diameter of thrust washer
G	M8	Thread
l <sub>G</sub>	10 mm	Thread length
d <sub>e</sub>	11 mm	Diameter of eccentric
B <sub>e</sub>	9 mm	Width, eccentric
e	0,5 mm	Eccentricity

### Additional information

	NIPA1	Drive-fit lubrication nipple
	1,5 mm	Protrusion lubrication nipple
M <sub>A</sub>	8 Nm	Tightening torque nut