

★ KRV19-PP


Yoke type track roller

Schaeffler ID:
0057437610000

★ Preferred product

Stud type track rollers KRV...-PP, with axial guidance, full complement needle roller set, plastic axial plain washers on both sides

Technical information

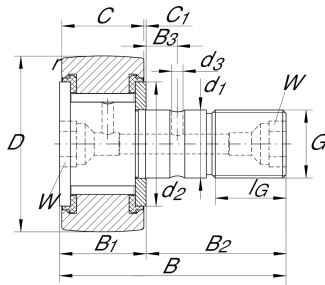

Main Dimensions & Performance Data

D	19 mm	Outside diameter
d ₁	8 mm	Fit diameter of roller stud / stud
B	32 mm	Width
C _{rw}	5.400 N	Basic dynamic load rating, radial
C _{orw}	8.100 N	Basic static load rating, radial
C _{urw}	1.190 N	Fatigue load limit, radial
n _{DG}	3.100 1/min	Speed on permanent grease lubrication
	28,754 g	Weight

Dimensions

B ₁	12,2 mm	Width of thrust washer
B ₂	20 mm	Bolt/stud length effectively
C	11 mm	Width, outer ring
C ₁	0,6 mm	Protrusion outer ring to thrust washer
r _{min}	0,15 mm	Minimum chamfer dimension
d ₂	15 mm	Stop diameter of thrust washer
G	M8	Thread
l _G	10 mm	Thread length

Additional information

	NIPA1	Drive-fit lubrication nipple
	1,5 mm	Protrusion lubrication nipple
M _A	8 Nm	Tightening torque nut