

★ KRE26-PP


Yoke type track roller

Schaeffler ID:
0057478720000

★ Preferred product

Stud type track rollers KRE...-PP, with axial guidance, with eccentric collar, plastic axial plain washers on both sides

Technical information

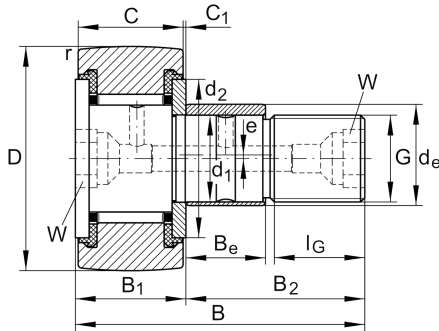

Main Dimensions & Performance Data

D	26 mm	Outside diameter
d ₁	10 mm	Fit diameter of roller stud / stud
B	36 mm	Width
C _{r w}	5.100 N	Basic dynamic load rating, radial
C _{0r w}	6.500 N	Basic static load rating, radial
C _{ur w}	860 N	Fatigue load limit, radial
n _{DG}	8.000 1/min	Speed on permanent grease lubrication
	58,844 g	Weight

Dimensions

B ₁	13,2 mm	Width of thrust washer
B ₂	23 mm	Bolt/stud length effectively
C	12 mm	Width, outer ring
C ₁	0,6 mm	Protrusion outer ring to thrust washer
r _{min}	0,3 mm	Minimum chamfer dimension
d ₂	17,5 mm	Stop diameter of thrust washer
G	M10X1	Thread
l _G	12 mm	Thread length
W	5 mm	Nominal dimension for hexagonal socket
d _e	13 mm	Diameter of eccentric
B _e	10 mm	Width, eccentric
e	0,5 mm	Eccentricity

Additional information

	NIPA1X4,5	Drive-fit lubrication nipple
M _A	15 Nm	Tightening torque nut