

★ KRV26-PP


Yoke type track roller

Schaeffler ID:
0057495650000

★ Preferred product

Stud type track rollers KRV...-PP, with axial guidance, full complement needle roller set, plastic axial plain washers on both sides

Technical information

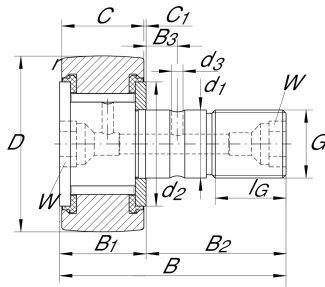

Main Dimensions & Performance Data

| | | |
|-------------------|-------------|---------------------------------------|
| D | 26 mm | Outside diameter |
| d ₁ | 10 mm | Fit diameter of roller stud / stud |
| B | 36 mm | Width |
| C _{r w} | 7.300 N | Basic dynamic load rating, radial |
| C _{0r w} | 11.600 N | Basic static load rating, radial |
| C _{ur w} | 1.520 N | Fatigue load limit, radial |
| n _{D G} | 2.600 1/min | Speed on permanent grease lubrication |
| | 55,924 g | Weight |

Dimensions

| | | |
|------------------|---------|--|
| B ₁ | 13,2 mm | Width of thrust washer |
| B ₂ | 23 mm | Bolt/stud length effectively |
| C | 12 mm | Width, outer ring |
| C ₁ | 0,6 mm | Protrusion outer ring to thrust washer |
| r _{min} | 0,3 mm | Minimum chamfer dimension |
| d ₂ | 17,5 mm | Stop diameter of thrust washer |
| G | M10X1 | Thread |
| l _G | 12 mm | Thread length |
| W | 5 mm | Width of flats |

Additional information

| | | |
|----------------|-----------|------------------------------|
| | NIPA1X4,5 | Drive-fit lubrication nipple |
| M _A | 15 Nm | Tightening torque nut |