

## ★ NUKR72


### Yoke type track roller

Schaeffler ID:  
0095962320000

★ Preferred product

Stud type track rollers NUKR, with axial guidance, full complement cylindrical roller set, labyrinth seals on both sides

## Technical information

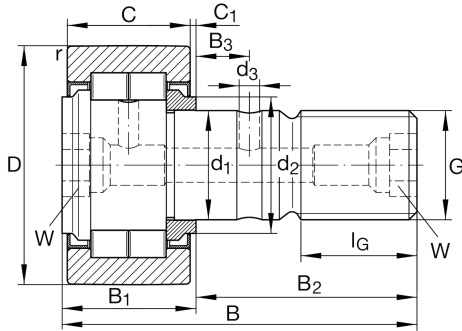

### Main Dimensions & Performance Data

D	72 mm	Outside diameter
d <sub>1</sub>	24 mm	Fit diameter of roller stud / stud
B	80 mm	Width
C <sub>rw</sub>	45.000 N	Basic dynamic load rating, radial
C <sub>orw</sub>	66.000 N	Basic static load rating, radial
C <sub>urw</sub>	8.900 N	Fatigue load limit, radial
n <sub>DG</sub>	2.600 1/min	Speed on permanent grease lubrication
F <sub>orper</sub>	62.000 N	Permissible static load, radial
F <sub>rper</sub>	31.500 N	Permissible dynamic load outer ring, radial
	0,986 kg	Weight

### Dimensions

B <sub>1</sub>	30,6 mm	Width of thrust washer
B <sub>2</sub>	49,5 mm	Bolt/stud length effectively
B <sub>3</sub>	11 mm	Distance to lubrication hole
C	28 mm	Width, outer ring
C <sub>1</sub>	1,3 mm	Protrusion outer ring to thrust washer
r <sub>min</sub>	1,1 mm	Minimum chamfer dimension
d <sub>2</sub>	44 mm	Stop diameter of thrust washer
d <sub>3</sub>	4 mm	Diameter lubrication hole
G	M24X1,5	Thread
l <sub>G</sub>	25 mm	Thread length
W	14 mm	Width of flats

### Additional information

	NIPA3X9,5	Drive-fit lubrication nipple
M <sub>A</sub>	220 Nm	Tightening torque nut