

★ PWKR72-2RS-XL

Yoke type track roller


Schaeffler ID:
0645546430000

★ Preferred product

Stud type track rollers PWKR..-2RS, with axial guidance, full complement cylindrical roller set, lip seals on both sides

X-life

Technical information

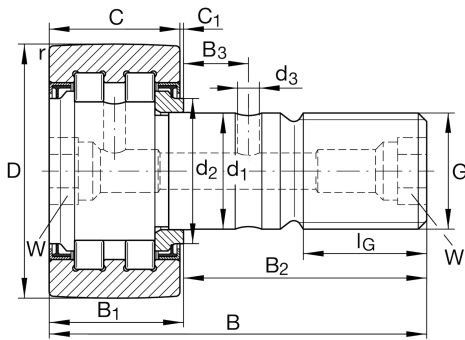

Main Dimensions & Performance Data

D	72 mm	Outside diameter
d ₁	24 mm	Fit diameter of roller stud / stud
B	80 mm	Width
C _{r w}	39.000 N	Basic dynamic load rating, radial
C _{0r w}	55.000 N	Basic static load rating, radial
C _{ur w}	7.100 N	Fatigue load limit, radial
n _{D G}	2.200 1/min	Speed on permanent grease lubrication
F _{0r per}	55.000 N	Permissible static load, radial
F _{r per}	38.500 N	Permissible dynamic load outer ring, radial
	0,969 kg	Weight

Dimensions

B ₁	30,6 mm	Width of thrust washer
B ₂	49,5 mm	Bolt/stud length effectively
B ₃	11 mm	Distance to lubrication hole
C	28 mm	Width, outer ring
C ₁	1,3 mm	Protrusion outer ring to thrust washer
r _{min}	1,1 mm	Minimum chamfer dimension
d ₂	44 mm	Stop diameter of thrust washer
d ₃	4 mm	Diameter lubrication hole
G	M24X1,5	Thread
l _G	25 mm	Thread length
W	14 mm	Width of flats

Additional information

	NIPA3X9,5	Drive-fit lubrication nipple
M _A	220 Nm	Tightening torque nut