



★ RATRY30-XL

Flanged housing unit



Schaeffler ID:
0008853710000

★ Preferred product

Housing units RATRY, three-bolt flanged housing units, sheet steel, grub screws in inner ring, P seals

X-life

Technical information

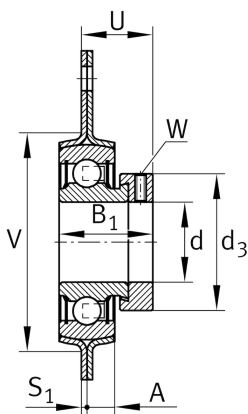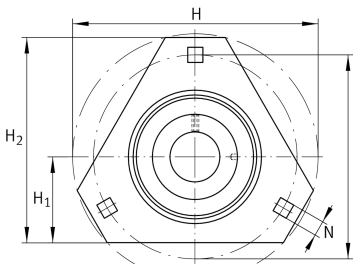

Main Dimensions & Performance Data

d	30 mm	Bore diameter
H ₂	93 mm	Height flange
H	112,7 mm	Height flange
H	112,7 mm	Flange width
U	23,5 mm	Total height unit
C _r	20.700 N	Basic dynamic load rating, radial
C _{0r}	11.300 N	Basic static load rating, radial
C _{0rG}	5.000 N	Load carrying capacity (housing)
C _g	5.000 N	Load carrying capacity (housing)
	0,45 kg	Weight

Dimensions

A	8,7 mm	Height housing
H ₁	38,1 mm	Distance shaft axis
S	2,5 mm	Thickness of flange
V	71 mm	Shoulder diameter housing

Mounting dimensions

J	90,5 mm	Distance fixing bore
J	90,5 mm	Pitch circle diameter (holes)
N	10,5 mm	Fixing square
n	3	Number of screwing holes

Additional information

	2	Number of housings
	FLAN62-MSTR	Housing
	AY30-XL-NPP-B	Bearing designation