



★ PME30-XL-N

Flanged housing unit


Schaeffler ID:
0074430990000

Housing units PME, four-bolt flanged housing units, cast iron, centring spigot, eccentric locking collar, P seals

★ Preferred product

X-life

Technical information

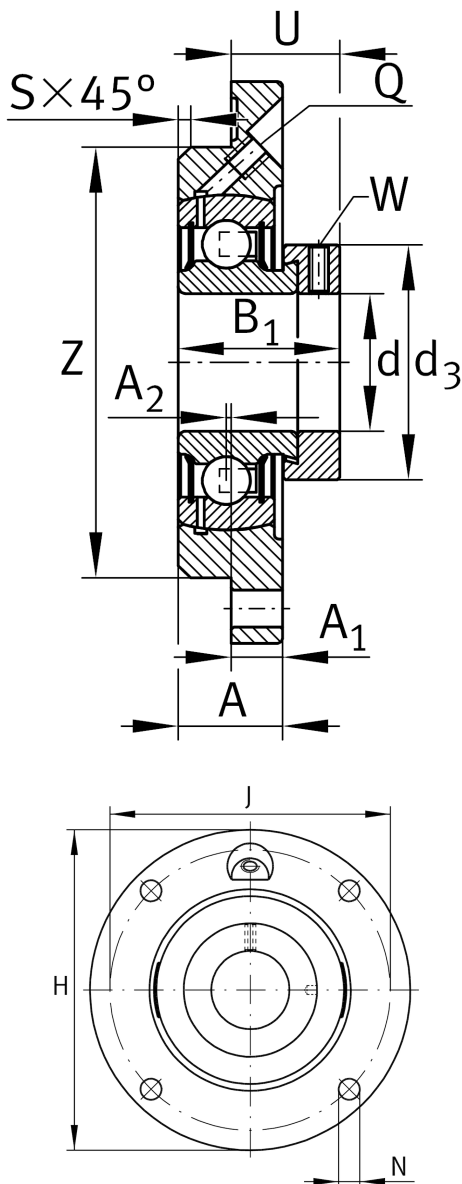

Main Dimensions & Performance Data

d	30 mm	Bore diameter
H	125 mm	Height flange
B ₁	35,8 mm	Locking collar total width
U	24,7 mm	Total height unit
C _r	19.500 N	Basic dynamic load rating, radial
C _{0r}	11.300 N	Basic static load rating, radial
C _{ur}	480 N	Fatigue load limit, radial
	0,97 kg	Weight

Dimensions

A	20,5 mm	Height housing
A ₁	9,5 mm	Thickness of flange
A ₂	2 mm	Distance raceway
S	2 mm	Chamfer width
Q	M6	Connection thread lubrication

Mounting dimensions

J	100 mm	Pitch circle diameter (holes)
N	11,5 mm	Fixing bore
T ₁	11 mm	Height spigot
Z	80 mm	Diameter spigot
	h8	Diameter spigot clearance
n	4	Number of screwing holes

Additional information

1	Number of housings
ME06	Housing
GRAE30-XL-NPP-B	Bearing designation
KASK06	Protecting cap