



★ 202-XL-KRR

Deep groove ball bearing


Schaeffler ID:
0008072060000

★ Preferred product

Radial insert ball bearings 2..-KRR,
cylindrical outer ring, inner ring for fit, R
seals on both sides

X-life

Technical information

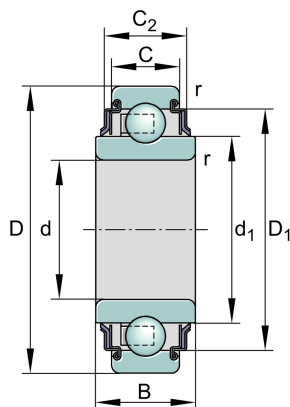

Main Dimensions & Performance Data

d	15 mm	Bore diameter
D	35 mm	Outside diameter
B	14,4 mm	Width
C_r	8.100 N	Basic dynamic load rating, radial
C_{0r}	3.700 N	Basic static load rating, radial
$n_{G \text{ Grease}}$	25.500 1/min	Limiting speed for grease lubrication
	0,05 kg	Weight

Dimensions

D_1	28,8 mm	Outside diameter seal
C	11 mm	Width, outer ring
C_2	11 mm	Sealing total width
d_1	21,5 mm	Rib diameter inner ring

Calculation factors

f_0	13,1	Calculation factor
-------	------	--------------------