



★ 204-XL-KRR

Deep groove ball bearing


Schaeffler ID:
0008092250000

★ Preferred product

Radial insert ball bearings 2..-KRR,
cylindrical outer ring, inner ring for fit, R
seals on both sides

X-life

Technical information

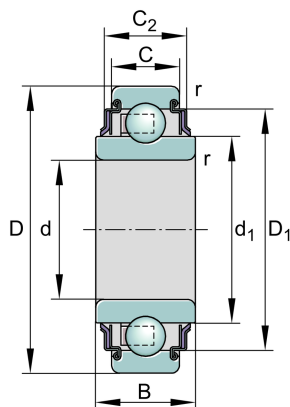

Main Dimensions & Performance Data

d	20 mm	Bore diameter
D	47 mm	Outside diameter
B	17,7 mm	Width
C_r	12.800 N	Basic dynamic load rating, radial
C_{0r}	6.600 N	Basic static load rating, radial
$n_{G \text{ Grease}}$	18.800 1/min	Limiting speed for grease lubrication
	0,11 kg	Weight

Dimensions

D_1	38,7 mm	Outside diameter seal
C	14 mm	Width, outer ring
C_2	14 mm	Sealing total width
d_1	28,7 mm	Rib diameter inner ring

Calculation factors

f_0	13,1	Calculation factor
-------	------	--------------------