



## ★ 206-XL-KRR

Deep groove ball bearing


Schaeffler ID:  
0008115210000

★ Preferred product

Radial insert ball bearings 2..-KRR,  
cylindrical outer ring, inner ring for fit, R  
seals on both sides

X-life

### Technical information

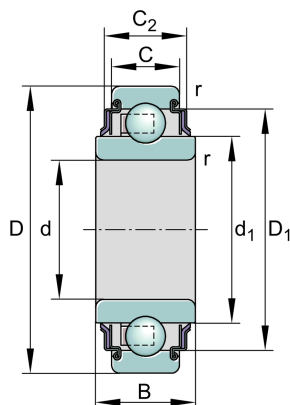

#### Main Dimensions & Performance Data

d	30 mm	Bore diameter
D	62 mm	Outside diameter
B	24 mm	Width
$C_r$	20.700 N	Basic dynamic load rating, radial
$C_{0r}$	11.300 N	Basic static load rating, radial
$n_{G \text{ Grease}}$	13.800 1/min	Limiting speed for grease lubrication
	0,24 kg	Weight

#### Dimensions

$D_1$	52 mm	Outside diameter seal
C	16 mm	Width, outer ring
$C_2$	19,6 mm	Sealing total width
$d_1$	40,2 mm	Rib diameter inner ring

#### Calculation factors

$f_0$	13,8	Calculation factor
-------	------	--------------------