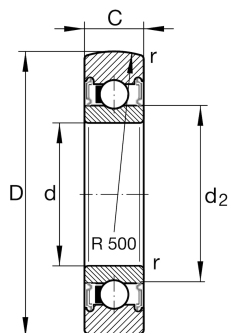
**LR206-X-2RS**

Track roller

Schaeffler ID:
0008118310000Track roller LR..-2RSR, single row, no
plastic tyre

Technical information

**Main Dimensions & Performance Data**

D	72 mm	Outside diameter
d	30 mm	Bore diameter
C	16 mm	Height
$C_{r w}$	17.600 N	Basic dynamic load rating, radial
$C_{0r w}$	9.900 N	Basic static load rating, radial
$C_{ur w}$	510 N	Fatigue load limit, radial
n_{DG}	5.500 1/min	Speed on permanent grease lubrication
	0,33 kg	Weight

Dimensions

d_2	37,4 mm	Diameter of thrust washer
r_{min}	1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile