

★ LR209-2RS


Track roller

Schaeffler ID:
0008155430000

Track roller LR...-2RSR, single row, no plastic tyre

★ Preferred product

Technical information

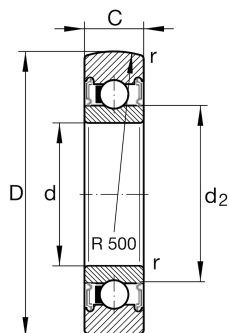

Main Dimensions & Performance Data

D	90 mm	Outside diameter
d	45 mm	Bore diameter
C	19 mm	Height
$C_{r w}$	23.700 N	Basic dynamic load rating, radial
$C_{0r w}$	14.100 N	Basic static load rating, radial
$C_{ur w}$	750 N	Fatigue load limit, radial
n_{DG}	3.600 1/min	Speed on permanent grease lubrication
	0,5 kg	Weight

Dimensions

d_2	53,2 mm	Diameter of thrust washer
r_{min}	1,1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile