

## ★ LR209-X-2RS


Track roller

Schaeffler ID:  
0008155780000

Track roller LR...-2RSR, single row, no plastic tyre

★ Preferred product

### Technical information

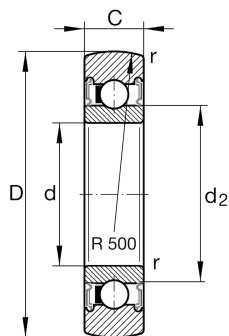

#### Main Dimensions & Performance Data

D	90 mm	Outside diameter
d	45 mm	Bore diameter
C	19 mm	Height
$C_{r w}$	23.700 N	Basic dynamic load rating, radial
$C_{0r w}$	14.100 N	Basic static load rating, radial
$C_{ur w}$	750 N	Fatigue load limit, radial
$n_{DG}$	3.600 1/min	Speed on permanent grease lubrication
	0,5 kg	Weight

#### Dimensions

$d_2$	53,2 mm	Diameter of thrust washer
$r_{min}$	1,1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile