



## ★ GRAE17-XL-NPP-B

Radial insert ball bearing


Schaeffler ID:  
0008493160000

Radial insert ball bearing GRAE...XL-NPP-B

★ Preferred product

X-life

### Technical information

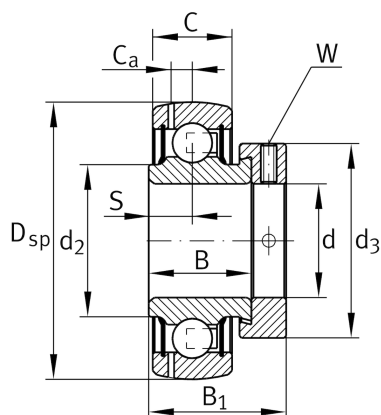

#### Main Dimensions & Performance Data

d	17 mm	Bore diameter
D <sub>SP</sub>	40 mm	Outside diameter
B	19 mm	Width
B <sub>1</sub>	28,6 mm	Locking collar total width
n <sub>G Grease</sub>	22.300 1/min	Limiting speed for grease lubrication
C <sub>r</sub>	9.800 N	Basic dynamic load rating, radial
C <sub>or</sub>	4.750 N	Basic static load rating, radial
C <sub>ur</sub>	248 N	Fatigue load limit, radial
	0,1 kg	Weight

#### Dimensions

C	12 mm	Width, outer ring
S	6,5 mm	Distance raceway
d <sub>2</sub>	23 mm	Rib diameter sealing inner ring
C <sub>a</sub>	3,4 mm	Distance to lubrication hole
d <sub>3</sub>	28,4 mm	Outside diameter locking collar/locknut
W	3 mm	Width of flats

#### Additional information

f <sub>0</sub>	13	Calculation factor
----------------	----	--------------------