



★ GLE25-XL-KRR-B

Radial insert ball bearing


Schaeffler ID:
0008527910000

★ Preferred product

Radial insert ball bearings GLE..-KRR-B, spherical outer ring, non-locating bearing, drive slot in inner ring, R seals on both sides

X-life

Technical information

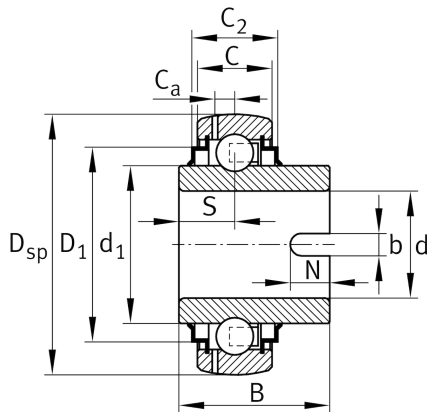

Main Dimensions & Performance Data

d	25 mm	Bore diameter
D _{SP}	52 mm	Outside diameter
B	34,9 mm	Width
n _{G Grease}	16.700 1/min	Limiting speed for grease lubrication
C _r	14.900 N	Basic dynamic load rating, radial
C _{0r}	7.800 N	Basic static load rating, radial
C _{ur}	410 N	Fatigue load limit, radial
	0,19 kg	Weight

Dimensions

C	15 mm	Width, outer ring
C ₂	16,7 mm	Sealing total width
S	14,7 mm	Distance raceway
d ₁	33,8 mm	Rib diameter inner ring
D ₁	42,5 mm	Outside diameter seal
C _a	3,9 mm	Distance to lubrication hole
N	8 mm	Hight retaining slot
b	7 mm	Width retaining slot
	H11	Width retaining slot clearance

Additional information

f ₀	13,8	Calculation factor
----------------	------	--------------------