



## ★ GLE30-XL-KRR-B

Radial insert ball bearing


Schaeffler ID:  
0008528560000

★ Preferred product

Radial insert ball bearings GLE..-KRR-B, spherical outer ring, non-locating bearing, drive slot in inner ring, R seals on both sides

X-life

### Technical information

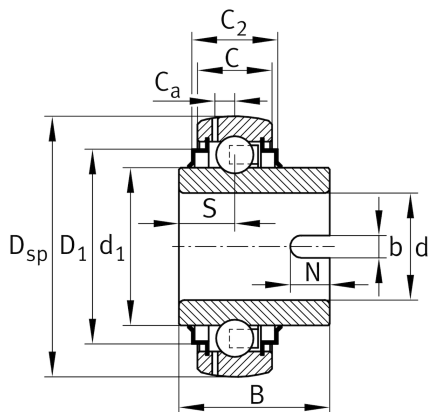

### Main Dimensions & Performance Data

d	30 mm	Bore diameter
D <sub>SP</sub>	62 mm	Outside diameter
B	36,5 mm	Width
n <sub>G Grease</sub>	13.800 1/min	Limiting speed for grease lubrication
C <sub>r</sub>	19.500 N	Basic dynamic load rating, radial
C <sub>0r</sub>	11.300 N	Basic static load rating, radial
C <sub>ur</sub>	520 N	Fatigue load limit, radial
	0,3 kg	Weight

### Dimensions

C	18 mm	Width, outer ring
C <sub>2</sub>	20,7 mm	Sealing total width
S	14,5 mm	Distance raceway
d <sub>1</sub>	40,2 mm	Rib diameter inner ring
D <sub>1</sub>	52 mm	Outside diameter seal
C <sub>a</sub>	4,7 mm	Distance to lubrication hole
N	8 mm	Hight retaining slot
b	7 mm	Width retaining slot
	H11	Width retaining slot clearance

### Additional information

f <sub>0</sub>	13,8	Calculation factor
----------------	------	--------------------