



★ GLE40-XL-KRR-B

Radial insert ball bearing


Schaeffler ID:
0008529530000

★ Preferred product

Radial insert ball bearings GLE..-KRR-B, spherical outer ring, non-locating bearing, drive slot in inner ring, R seals on both sides

X-life

Technical information

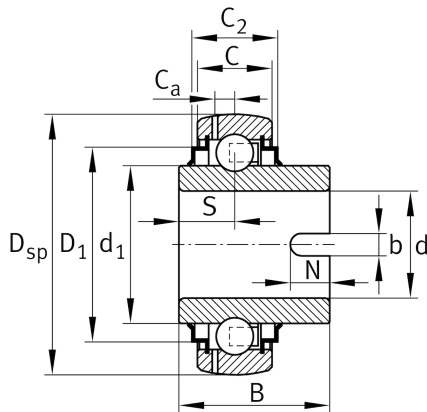

Main Dimensions & Performance Data

d	40 mm	Bore diameter
D _{SP}	80 mm	Outside diameter
B	42,9 mm	Width
n _{G Grease}	10.300 1/min	Limiting speed for grease lubrication
C _r	34.500 N	Basic dynamic load rating, radial
C _{0r}	19.800 N	Basic static load rating, radial
C _{ur}	910 N	Fatigue load limit, radial
	0,56 kg	Weight

Dimensions

C	21 mm	Width, outer ring
C ₂	23,5 mm	Sealing total width
S	15,9 mm	Distance raceway
d ₁	52,3 mm	Rib diameter inner ring
D ₁	68,3 mm	Outside diameter seal
C _a	6,4 mm	Distance to lubrication hole
N	9 mm	Hight retaining slot
b	7 mm	Width retaining slot
	H11	Width retaining slot clearance

Additional information

f ₀	13,6	Calculation factor
----------------	------	--------------------