

★ LR50/6-2RSR


Track roller

Schaeffler ID:
0008627200000

★ Preferred product

Track rollers LR50, double row, sealed on both sides

Technical information

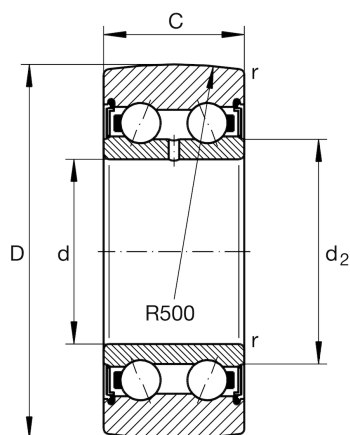

Main Dimensions & Performance Data

D	19 mm	Outside diameter
d	6 mm	Bore diameter
C	9 mm	Height
$C_{r w}$	2.700 N	Basic dynamic load rating, radial
$C_{0r w}$	1.410 N	Basic static load rating, radial
$C_{ur w}$	68 N	Fatigue load limit, radial
n_{DG}	11.000 1/min	Speed on permanent grease lubrication
$F_{r per}$	1.410 N	Permissible dynamic load outer ring, radial
	12,79 g	Weight

Dimensions

d_2	9,3 mm	Diameter of thrust washer
r_{min}	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile