

★ ZL202-DRS


Stud type track roller

Schaeffler ID:
0009034850000

Stud type track roller ZL2...-DRS, single row, no eccentric

★ Preferred product

Technical information

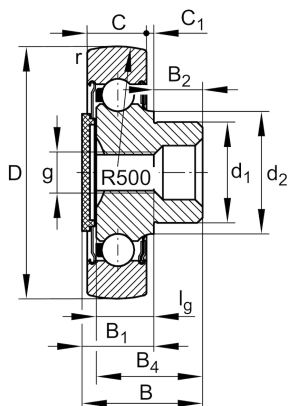

Main Dimensions & Performance Data

D	40 mm	Outside diameter
d ₁	16 mm	Fit diameter of roller stud / stud
B	23,8 mm	Width
C _{r w}	7.000 N	Basic dynamic load rating, radial
C _{0r w}	3.450 N	Basic static load rating, radial
C _{ur w}	175 N	Fatigue load limit, radial
n _{DG}	8.500 1/min	Speed on permanent grease lubrication
	0,08 kg	Weight

Dimensions

B _{1 max}	14 mm	Maximum width of thrust washer
B ₂	10 mm	Bolt/stud length effectively
B ₄	21,5 mm	Length total
C	11 mm	Width, outer ring
C ₁	2 mm	Protrusion outer ring to thrust washer
d ₂	20 mm	Stop diameter of thrust washer
r _{min}	0,6 mm	Minimum chamfer dimension
g	M8	Thread inside
l _g	15 mm	Thread length (inner)
R	500 mm	Radius of outer ring outside profile