

★ ZL204-DRS


Stud type track roller

Schaeffler ID:
0009037010000

Stud type track roller ZL2...-DRS, single row, no eccentric

★ Preferred product

Technical information

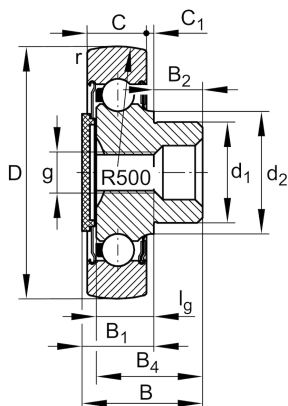

Main Dimensions & Performance Data

D	52 mm	Outside diameter
d ₁	20 mm	Fit diameter of roller stud / stud
B	30,7 mm	Width
C _{r w}	11.300 N	Basic dynamic load rating, radial
C _{0r w}	5.900 N	Basic static load rating, radial
C _{ur w}	300 N	Fatigue load limit, radial
n _{DG}	6.000 1/min	Speed on permanent grease lubrication
	0,17 kg	Weight

Dimensions

B _{1 max}	17 mm	Maximum width of thrust washer
B ₂	14 mm	Bolt/stud length effectively
B ₄	28,5 mm	Length total
C	14 mm	Width, outer ring
C ₁	2 mm	Protrusion outer ring to thrust washer
d ₂	26,8 mm	Stop diameter of thrust washer
r _{min}	1 mm	Minimum chamfer dimension
g	M10	Thread inside
l _g	18 mm	Thread length (inner)
R	500 mm	Radius of outer ring outside profile