

★ ZL205-DRS


Stud type track roller

Schaeffler ID:
0009037790000

Stud type track roller ZL2...-DRS, single
row, no eccentric

★ Preferred product

Technical information

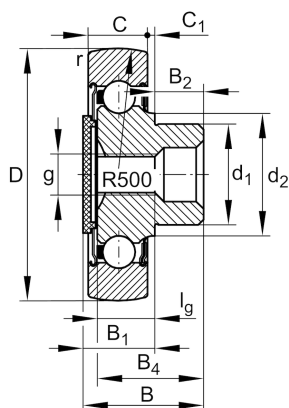

Main Dimensions & Performance Data

D	62 mm	Outside diameter
d ₁	25 mm	Fit diameter of roller stud / stud
B	33,8 mm	Width
C _{r w}	13.300 N	Basic dynamic load rating, radial
C _{0r w}	7.300 N	Basic static load rating, radial
C _{ur w}	370 N	Fatigue load limit, radial
n _{DG}	5.500 1/min	Speed on permanent grease lubrication
	0,25 kg	Weight

Dimensions

B _{1 max}	18 mm	Maximum width of thrust washer
B ₂	16 mm	Bolt/stud length effectively
B ₄	31 mm	Length total
C	15 mm	Width, outer ring
C ₁	2 mm	Protrusion outer ring to thrust washer
d ₂	30,3 mm	Stop diameter of thrust washer
r _{min}	1 mm	Minimum chamfer dimension
g	M10	Thread inside
l _g	19 mm	Thread length (inner)
R	500 mm	Radius of outer ring outside profile