

## ★ ZL5201-DRS


### Stud type track roller

Schaeffler ID:  
0009041200000

Stud type track rollers ZL52..-DRS, double row, lip seal on one side

★ Preferred product

## Technical information

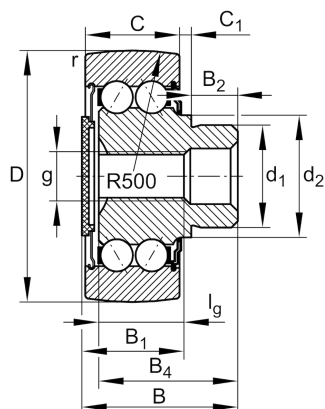

### Main Dimensions & Performance Data

D	35 mm	Outside diameter
d <sub>1</sub>	14 mm	Fit diameter of roller stud / stud
B	33,2 mm	Width
C <sub>rw</sub>	8.700 N	Basic dynamic load rating, radial
C <sub>orw</sub>	5.400 N	Basic static load rating, radial
C <sub>urw</sub>	270 N	Fatigue load limit, radial
n <sub>DG</sub>	7.500 1/min	Speed on permanent grease lubrication
	0,09 kg	Weight

### Dimensions

B <sub>1max</sub>	19,5 mm	Maximum width of thrust washer
B <sub>2</sub>	14 mm	Bolt/stud length effectively
B <sub>4</sub>	31 mm	Length total
C	15,9 mm	Width, outer ring
C <sub>1</sub>	2,6 mm	Protrusion outer ring to thrust washer
d <sub>2</sub>	17,1 mm	Stop diameter of thrust washer
r <sub>min</sub>	0,6 mm	Minimum chamfer dimension
g	M8	Thread inside
l <sub>g</sub>	14 mm	Thread length (inner)
R	500 mm	Radius of outer ring outside profile