

★ ZL5205-DRS


Stud type track roller

Schaeffler ID:
0009043920000

Stud type track rollers ZL52..-DRS, double row, lip seal on one side

★ Preferred product

Technical information

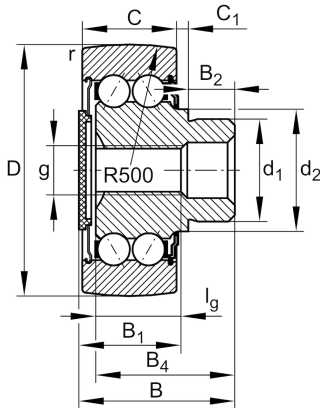

Main Dimensions & Performance Data

D	62 mm	Outside diameter
d ₁	25 mm	Fit diameter of roller stud / stud
B	50,4 mm	Width
C _{rw}	18.800 N	Basic dynamic load rating, radial
C _{orw}	13.600 N	Basic static load rating, radial
C _{urw}	690 N	Fatigue load limit, radial
n _{DG}	4.500 1/min	Speed on permanent grease lubrication
	0,38 kg	Weight

Dimensions

B _{1max}	25,5 mm	Maximum width of thrust washer
B ₂	25 mm	Bolt/stud length effectively
B ₄	47,5 mm	Length total
C	20,6 mm	Width, outer ring
C ₁	4 mm	Protrusion outer ring to thrust washer
d ₂	30,3 mm	Stop diameter of thrust washer
r _{min}	1 mm	Minimum chamfer dimension
g	M10	Thread inside
l _g	18 mm	Thread length (inner)
R	500 mm	Radius of outer ring outside profile