


LR6000-2RSR

Track roller

Schaeffler ID:
0009172140000

Track roller LR6..-2RSR, single row, no plastic tyre

Technical information

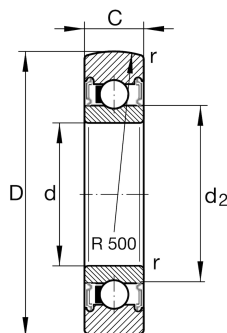

Main Dimensions & Performance Data

D	28 mm	Outside diameter
d	10 mm	Bore diameter
C	8 mm	Height
$C_{r w}$	5.000 N	Basic dynamic load rating, radial
$C_{0r w}$	2.550 N	Basic static load rating, radial
$C_{ur w}$	130 N	Fatigue load limit, radial
n_{DG}	16.000 1/min	Speed on permanent grease lubrication
	24 g	Weight

Dimensions

d_2	14,6 mm	Diameter of thrust washer
r_{min}	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile