

★ LR605-2RSR


Track roller

Schaeffler ID:
0009713670000

Track roller LR6..-2RSR, single row, no plastic tyre

★ Preferred product

Technical information

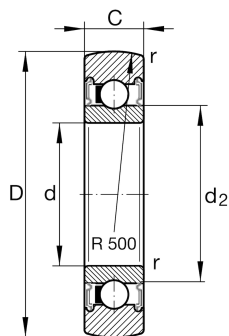

Main Dimensions & Performance Data

D	16 mm	Outside diameter
d	5 mm	Bore diameter
C	5 mm	Height
$C_{r w}$	1.290 N	Basic dynamic load rating, radial
$C_{0r w}$	510 N	Basic static load rating, radial
$C_{ur w}$	26,5 N	Fatigue load limit, radial
n_{DG}	23.000 1/min	Speed on permanent grease lubrication
	5,2 g	Weight

Dimensions

d_2	7,5 mm	Diameter of thrust washer
r_{min}	0,2 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile