



## ★ GRAE40-XL-NPP-B-FA125

Radial insert ball bearing


Schaeffler ID:  
0028281030000

Radial insert ball bearing GRAE...XL-NPP-  
B

★ Preferred product

X-life

### Technical information

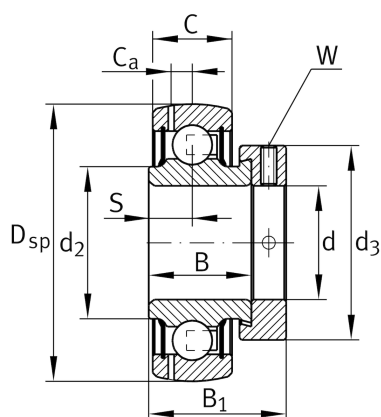

#### Main Dimensions & Performance Data

d	40 mm	Bore diameter
D <sub>SP</sub>	80 mm	Outside diameter
B	30,2 mm	Width
B <sub>1</sub>	43,8 mm	Locking collar total width
n <sub>G Grease</sub>	10.300 1/min	Limiting speed for grease lubrication
C <sub>r</sub>	34.500 N	Basic dynamic load rating, radial
C <sub>0r</sub>	19.800 N	Basic static load rating, radial
C <sub>ur</sub>	1.030 N	Fatigue load limit, radial
	0,62 kg	Weight

#### Dimensions

C	21 mm	Width, outer ring
S	11 mm	Distance raceway
d <sub>2</sub>	49,4 mm	Rib diameter sealing inner ring
C <sub>a</sub>	6,4 mm	Distance to lubrication hole
d <sub>3</sub>	58 mm	Outside diameter locking collar/locknut
W	5 mm	Width of flats

#### Additional information

f <sub>0</sub>	13,6	Calculation factor
----------------	------	--------------------