



IMAGE
COMING SOON




GRA107-NPP-B-AS2/V

Radial insert ball bearing

Schaeffler ID:
0502720800000

Radial insert ball bearing GRA...-NPP-B-
AS2/V

Technical information

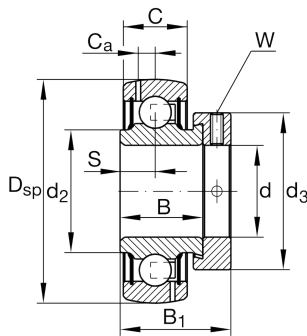

Main Dimensions & Performance Data

d	36,512 mm	Bore diameter
d	1.4375 inch	Bore diameter, inch
D _{SP}	72 mm	Outside diameter
B ₁	39 mm	Locking collar total width
B	25,4 mm	Width
C _{ur}	700 N	Fatigue load limit, radial
C _r	25.500 N	Basic dynamic load rating, radial
C _{0r}	15.300 N	Basic static load rating, radial
	0,004 kg	Weight

Dimensions

C	19 mm	Width, outer ring
S	9,5 mm	Distance raceway
d ₂	44,5 mm	Rib diameter sealing inner ring
C _a	5,7 mm	Distance to lubrication hole
d ₃	51 mm	Outside diameter locking collar/locknut
W	0.1875 inch	Width across flats (Inch)

Calculation factors

f ₀	13,8	Calculation factor
----------------	------	--------------------