

## ★ LR205-2RSR


Track roller

Schaeffler ID:  
0502741630000

Track roller LR...-2RSR, single row, no plastic tyre

★ Preferred product

### Technical information

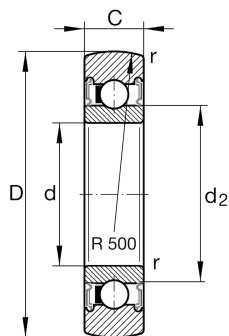

#### Main Dimensions & Performance Data

D	62 mm	Outside diameter
d	25 mm	Bore diameter
C	15 mm	Height
$C_{r w}$	13.300 N	Basic dynamic load rating, radial
$C_{0r w}$	7.300 N	Basic static load rating, radial
$C_{ur w}$	370 N	Fatigue load limit, radial
$n_{DG}$	7.000 1/min	Speed on permanent grease lubrication
	0,23 kg	Weight

#### Dimensions

$d_2$	33,5 mm	Diameter of thrust washer
$r_{min}$	1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile