



IMAGE
COMING SOON




★ NKIA5905-XL

Needle roller/angular contact ball bearing

Schaeffler ID:
0504211660000

★ Preferred product

Technical information

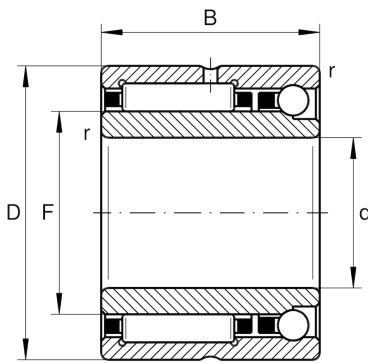

Main Dimensions & Performance Data

d	25 mm	Bore diameter
D	42 mm	Outside diameter
B	23 mm	Width
C_r	26.500 N	Basic dynamic load rating, radial
C_{0r}	31.500 N	Basic static load rating, radial
C_a	5.400 N	Basic dynamic load rating, axial
C_{0a}	9.300 N	Basic static load rating, axial
C_{ur}	5.800 N	Fatigue limit load, radial
C_{ur}	5.800 N	Fatigue load limit, radial
C_{ua}	420 N	Fatigue load limit, axial
n_G	14.600 1/min	Limiting speed
n_{gr}	12.000 1/min	Reference speed
	0,001 kg	Weight

Dimensions

F	30 mm	Raceway diameter inner ring
r_{min}	0,3 mm	Minimum chamfer dimension