



IMAGE  
COMING SOON




## ★ NKIA5908-XL

Needle roller/angular contact ball bearing

Schaeffler ID:  
0504211900000

★ Preferred product

### Technical information

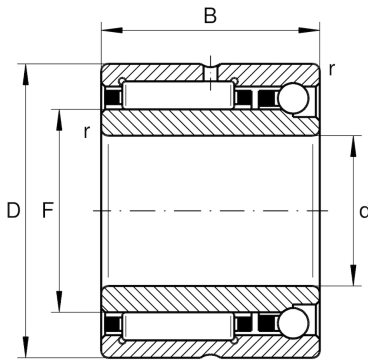

#### Main Dimensions & Performance Data

d	40 mm	Bore diameter
D	62 mm	Outside diameter
B	30 mm	Width
$C_r$	48.500 N	Basic dynamic load rating, radial
$C_{0r}$	67.000 N	Basic static load rating, radial
$C_a$	9.200 N	Basic dynamic load rating, axial
$C_{0a}$	19.400 N	Basic static load rating, axial
$C_{ur}$	11.700 N	Fatigue limit load, radial
$C_{ur}$	11.700 N	Fatigue load limit, radial
$C_{ua}$	880 N	Fatigue load limit, axial
$n_G$	9.600 1/min	Limiting speed
$n_{gr}$	7.500 1/min	Reference speed
	0,003 kg	Weight

#### Dimensions

F	48 mm	Raceway diameter inner ring
$r_{min}$	0,6 mm	Minimum chamfer dimension