



IMAGE
COMING SOON



★ NKIB59/22-XL

Needle roller/angular contact ball bearing


Schaeffler ID:
0504212800000

Needle roller/angular contact ball bearings
NKIB, double direction axial component

★ Preferred product

X-life

Technical information

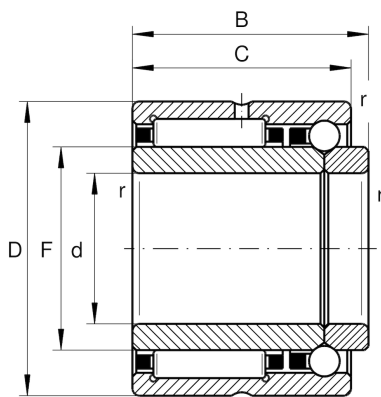

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,001 kg	Weight

Main Dimensions & Performance Data

d	22 mm	Bore diameter
D	39 mm	Outside diameter
B	25 mm	Width
C_r	26.000 N	Basic dynamic load rating, radial
C_{0r}	29.500 N	Basic static load rating, radial
C_a	5.300 N	Basic dynamic load rating, axial
C_{0a}	8.600 N	Basic static load rating, axial
C_{ur}	5.400 N	Fatigue load limit, radial
C_{ua}	395 N	Fatigue load limit, axial
n_G	16.100 1/min	Limiting speed
n_{gr}	12.000 1/min	Reference speed

Dimensions

F	28 mm	Raceway diameter inner ring
C	23 mm	Width, outer ring
r_{\min}	0,3 mm	Minimum chamfer dimension