

★ NA4902-XL

Needle roller bearing



Schaeffler ID:
0506595450000

Needle roller bearing NA49..-XL, single row, with inner ring, outer ring with 2 bords

★ Preferred product

X-life

Technical information

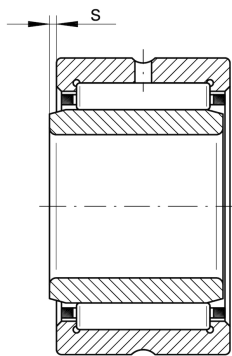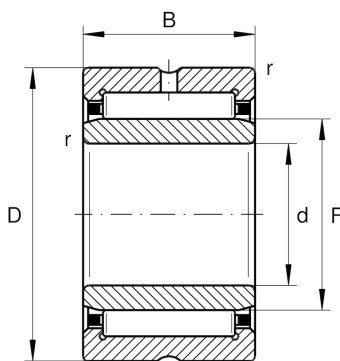

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,035 kg	Weight

Main Dimensions & Performance Data

d	15 mm	Bore diameter
D	28 mm	Outside diameter
B	13 mm	Width
C_r	12.000 N	Basic dynamic load rating, radial
C_{0r}	13.600 N	Basic static load rating, radial
C_{ur}	2.470 N	Fatigue load limit, radial
n_G	21.100 1/min	Limiting speed
n_{gr}	11.200 1/min	Reference speed

Dimensions

F	20 mm	Raceway diameter inner ring
r_{\min}	0,3 mm	Minimum chamfer dimension
s	0,5 mm	Axial displacement