



★ RNA6903-XL

Radial roller bearing


Schaeffler ID:
0507433410000

Radial roller bearing RNA..-XL

★ Preferred product

X-life

Technical information

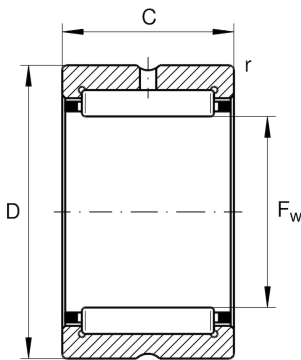

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,043 kg	Weight

Main Dimensions & Performance Data

F_w	22 mm	Under roller diameter
D	30 mm	Outside diameter
B	23 mm	Width
C_r	21.100 N	Basic dynamic load rating, radial
C_{0r}	29.000 N	Basic static load rating, radial
C_{ur}	5.200 N	Fatigue load limit, radial
n_G	20.000 1/min	Limiting speed
$n_{G \text{ Grease}}$	12.000 1/min	Limiting speed for grease lubrication
n_{gr}	10.500 1/min	Reference speed

Dimensions

r_{\min}	0,3 mm	Minimum chamfer dimension
C	23 mm	Width, outer ring

Additional information

G22X30X4	Sealing ring
SD22X30X4	Sealing ring 2