

★ RNA6908-ZW-XL

Radial roller bearing


Schaeffler ID:
0507435970000

Needle roller bearings RNA69...ZW,
Dimension series 69, double row

★ Preferred product

X-life

Technical information

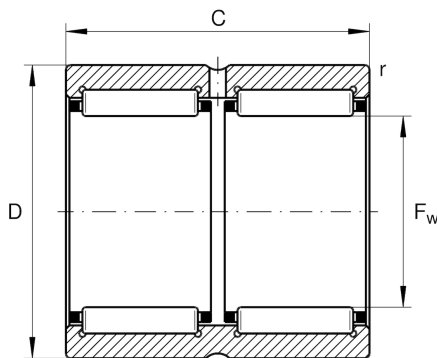

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,003 kg	Weight

Main Dimensions & Performance Data

F_w	48 mm	Under roller diameter
D	62 mm	Outside diameter
C_r	74.000 N	Basic dynamic load rating, radial
C_{0r}	116.000 N	Basic static load rating, radial
C_{ur}	19.800 N	Fatigue load limit, radial
n_G	9.200 1/min	Limiting speed
$n_{G \text{ Grease}}$	5.500 1/min	Limiting speed for grease lubrication
n_{gr}	5.400 1/min	Reference speed

Dimensions

r_{\min}	0,6 mm	Minimum chamfer dimension
C	40 mm	Width, outer ring