

## ★ NK22/16-XL

Needle roller bearing


Schaeffler ID:  
0507540410000

Needle roller bearings NK, light series

★ Preferred product

X-life

### Technical information

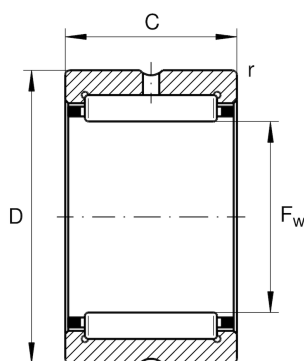

#### Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.
	0,029 kg	Weight

#### Main Dimensions & Performance Data

$F_w$	22 mm	Under roller diameter
$D$	30 mm	Outside diameter
$C$	16 mm	Width, outer ring
$C_r$	15.800 N	Basic dynamic load rating, radial
$C_{0r}$	19.900 N	Basic static load rating, radial
$C_{ur}$	3.750 N	Fatigue load limit, radial
$n_G$	20.000 1/min	Limiting speed
$n_{gr}$	12.000 1/min	Reference speed

#### Dimensions

$r_{\min}$	0,3 mm	Minimum chamfer dimension
------------	--------	---------------------------

#### Additional information

G22X30X4	Sealing ring
SD22X30X4	Sealing ring 2